




SERIES 701 SeaKing™ Junior High-Density PEEK Subsea Connectors



709-038 Pressure Cap Plug

HOW TO ORDER				
Sample Part Number	709-038	-17	-Z1	L
Product Series	709-038 = SeaKing Junior			
Shell Size	Xxxxxxx			
Material/Finish	Z1 = 316 Stainless Steel/Passivate* TC = Titanium			
Lanyard	Omit for None			

* 316 Stainless steel for sizes 09 through 15 2507 super duplex for sizes 17 through 25

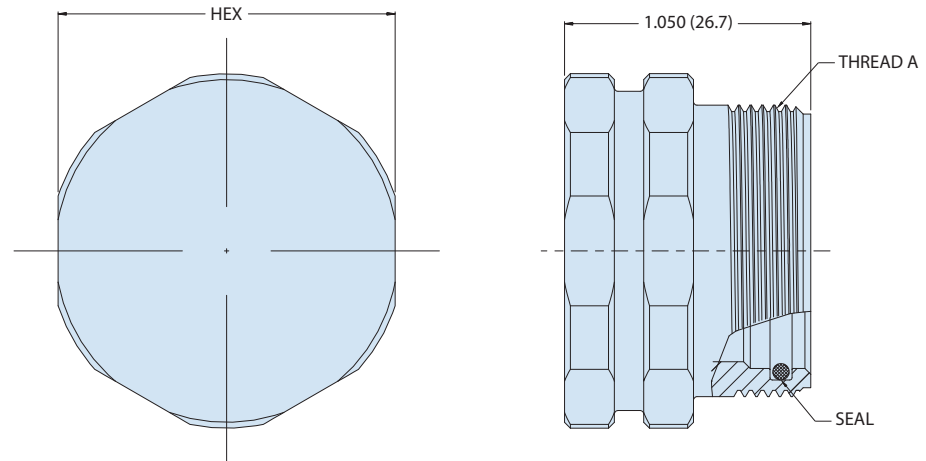

NOTES

Pressure rating: Mated condition -
5,000 PSI, tested per ISO 13628-6.

Materials tested to:

- Salt spray, per MIL-STD-202 method 101
- Humidity, per MIL-STD-202 method 101
- Thermal cycle, per EIA-455-71

Single O-ring sealing.

Mates to 701-011 series SeaKing junior
plugs of same size and polarization

MATERIAL/FINISH

Receptacle shell: see How to Order
Table

Seals: nitirle

DIMENSIONS				
Shell Size	Thread A	Hex		Bore Seal
		inch	mm	
09	0.7500-20 UN-2A	15/16	23.8	2-014
11	0.8750-20 UN-2A	1 1/16	27.0	2-016
13	1.0000-20 UNEF-2A	1 3/16	30.2	2-018
15	1.1250-20 UN-2A	1 5/16	33.3	2-020
17	1.2500-20 UN-2A	1 7/16	36.5	2-022
19	1.3750-20 UN-2A	1 9/16	39.7	2-024
21	1.5000-20 UN-2A	1 11/16	42.9	2-026
23	1.6250-20 UN-2A	1 13/16	46.0	2-028
25	1.7500-20 UN-2A	1 15/16	49.2	2-029