




DEEP WATER SeaKing™ Fiber Optic




10K PSI open-face pressure-rated fiber optic connectors, cables, transceivers, and media converters


ENVIRONMENTAL OVERMOLDED FIBER OPTIC JUMPERS

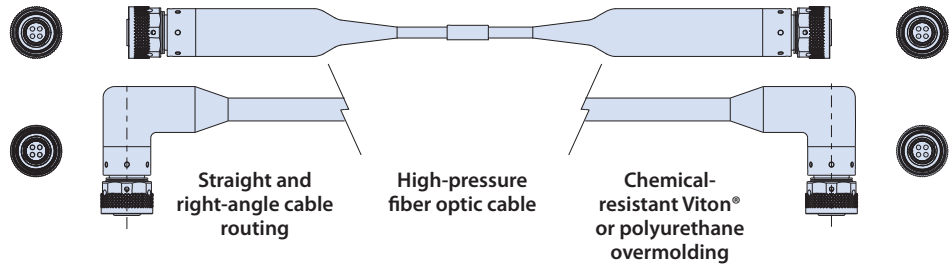

PRESSURE-BALANCED OIL-FILLED (PBOF) HIGH-PRESSURE FIBER OPTIC ASSEMBLIES

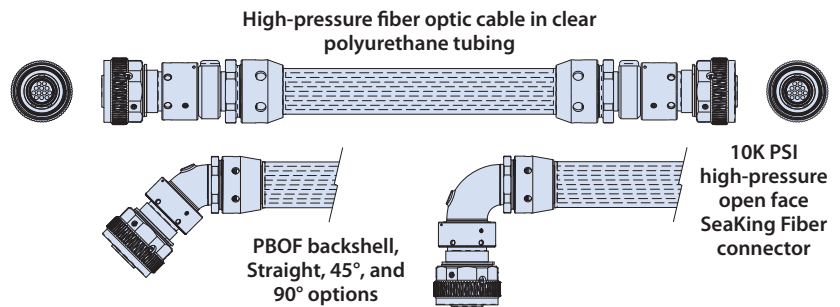


SEAKING™ BCR OR FCR TO COMMERCIAL FIBER OPTIC PIGTAIL ASSEMBLY FOR I/O-TO-BOARD MODULE APPLICATIONS

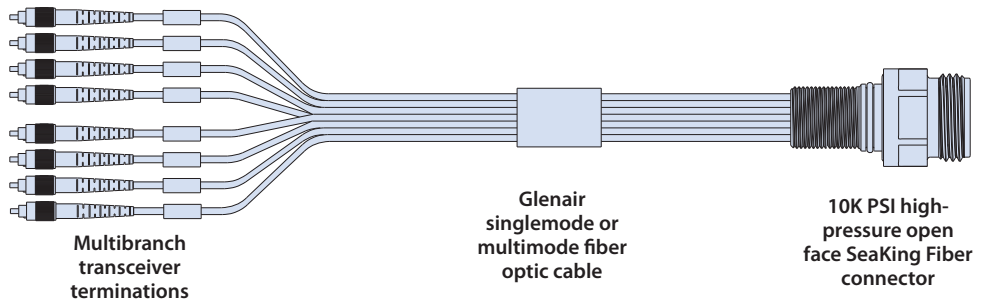


KEY AND KEYWAY POSITIONS

Alternate Keyway Positions		
Key Position	Key Rotation	
	A°	B°
Normal (N)	150°	210°
A	75°	210°
B	95°	230°
C	140°	275°

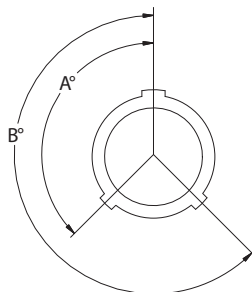

Plug (Key)

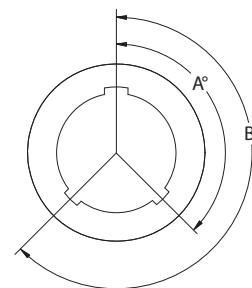

Receptacle (Keyway)