


"ZERO-CROSSTALK"
VersaLink™ Bridge Board Connectors

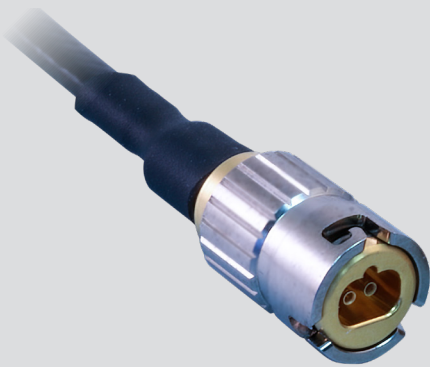

853-064 Bayonet, Socket Plug

VERSALINK BRIDGE



PART NUMBER DEVELOPMENT		
Sample Part Number		853-064 -01
Series	853-064 = Bayonet Coupling, Board Level Socket Plug	
Dash No	-01 = 963-069-26 -02 = 963-068-26	

RECOMMENDED CABLES						
Dash No	Cable P/N	Cable Construction	Wire Gauge	Max Overall Size	Crimp Die	Assembly Instructions
-01	963-069-26	Double Shielded Parallel Pair	26	.133 x .083	859-205	AI85153
-02	963-068-26	Double Shielded Twisted Pair	26	.133 x .083	859-205	AI85153

MATERIALS AND FINISHES

- Contacts: copper alloy/gold
- Insulators: superior rigid dielectric
- Body: copper alloy/gold
- Coupling nut: copper alloy/electroless nickel
- Spring: stainless steel

PERFORMANCE SPECIFICATIONS

- Operating temperature: -65°C to 150°C
- Mates with 853-065 and 853-067

NOTES

1. Contact factory to inquire about use with other cables.
2. Crimp tools:
 - » Inner contacts: 809-464
 - » Die: 859-205

