

968-001


27500 Type With Specialty Braid

NOTES

1. Consult factory for cable diameters exceeding 0.375 inches.
2. Number of conductors is dependent on maximum cable diameter capabilities. Consult factory for capabilities.

HOW TO ORDER						
Sample Part Number	968-001	-	22	TE	2	AR 14
Basic Part Number	968-001					
Identification Method	See Table IV					
Conductor Size	See Table I					
Basic Wire Description	See Table I					
Number Of Conductors	See Table I					
Shield Description	See Table II					
Jacket Type	See Table III					

Single Jacket Code	Double Jacket Code	Jacket Material Description
00	00	No Jacket
05	55	Extruded FEP, Clear
09	59	Extruded FEP, White
10	60	Extruded PVDF, Clear
14	64	Extruded ETFE, White
15	65	Extruded ETFE, Clear
20	70	Extruded PFA, White
21	71	Extruded PFA, Clear
23	73	Extruded Xletfe, White

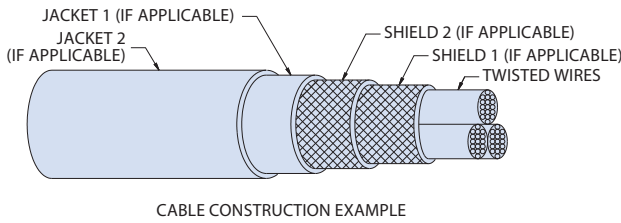

Code	Description
-	85% Coverage, White Wire with Colored Stripes
A	85% Coverage, Solid Colored White
C	90% Coverage, White Wire with Colored Stripes
D	90% Coverage, Solid Colored White

Code	Wire Type	AWG	# Of Conductors
TE	M22759/16 or GS22759-16	8 to 24	1,2,3,4,5
TF	M22759/17 or GS22759-17	20 to 26	1,2,3,4,5
TG	M22759/18 or GS22759-18	10 to 26	1,2,3,4,5
TH	M22759/19 or GS22759-19	20 to 26	1,2,3,4,5
SB	M22759/32 or GS22759-32	12 to 30	1,2,3,4,5
SC	M22759/33 or GS22759-33	20 to 30	1,2,3,4,5
SD	M22759/34 or GS22759-34	8 to 24	1,2,3,4,5
SE	M22759/35 or GS22759-35	20 to 26	1,2,3,4,5
SM	M22759/41 or GS22759-41	8 to 26	1,2,3,4,5
SN	M22759/42 or GS22759-42	20 to 26	1,2,3,4,5
SP	M22759/43 or GS22759-43	8 to 26	1,2,3,4,5
SR	M22759/44 or GS22759-44	12 to 28	1,2,3,4,5
SS	M22759/45 or GS22759-45	12 to 28	1,2,3,4,5
ST	M22759/46 or GS22759-46	20 to 28	1,2,3,4,5

Single Shield Code	Double Shield Code	Shield Description
AM	AS	AmberStrand®, Round
AR	AL	ArmorLite™, Round
AC	AF	ArmorLite™ CF, Round
U	U	Unshielded