

SPECIALTY WIRE AND CABLE





SGEMP-Resistant Wire

No air gaps • Duraelectric filler • ArmorLite shielding
Wire configurations / How to order

SGEMP-RESISTANT WIRE, SINGLE-CONDUCTOR OR TWISTED-PAIR • 968-060

Table II: Duraelectric™ D Jacket Color		
Weatherproof, halogen free, flame resistant, functional to 260°C		
0	Black	Fed-Std-595C #17038
1	Brown	[TBD]
2	Red	Fed-Std-595C #11120
3	Orange	Fed-Std-595C #12300
4	Yellow	Fed-Std-595C #13591
5	Kelly Green	Fed-Std-595C #14193
6	Blue	Fed-Std-595C #15125
7	Violet	Fed-Std-595C #17142
8	Gray	Fed-Std-595C #26270
9	White	Fed-Std-595C #17875

How To Order SGEMP-Resistant Wire				
Sample Part Number	968-060	-2	-26	-9
Basic Part No.	SGEMP-Resistant Wire			
No. of Conductors	1 Conductor = White 2 Conductors = White, Blue 3 Conductors = White, Blue, Orange 4 Conductors = White, Blue, Orange, Green			
Wire Gauge (AWG)	20, 22, 24, 26, 28, 30			
Duraelectric Jacket Color	See Table II			

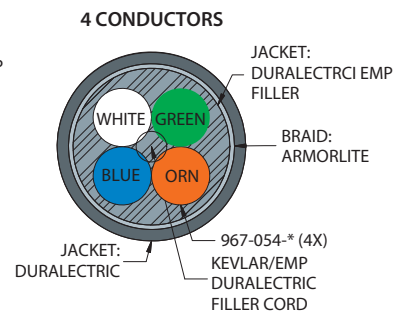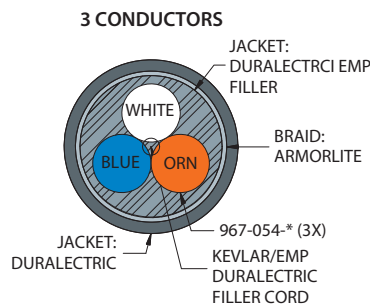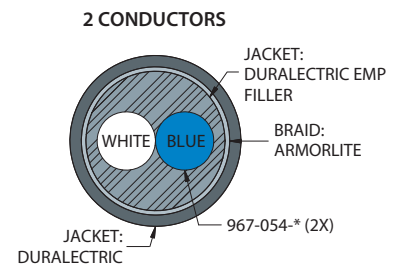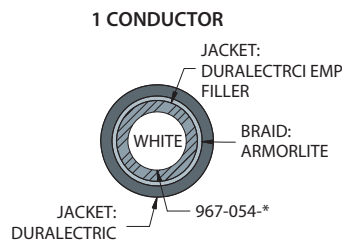

SPECIALTY WIRE AND CABLE